

分类

开关电源


保险丝

铁氧体磁环


尺寸图

(单位: mm)


ESP20-10-*(10W)

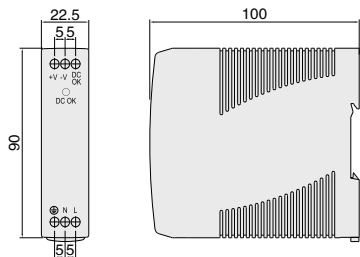


ESP20-100-*(100W)

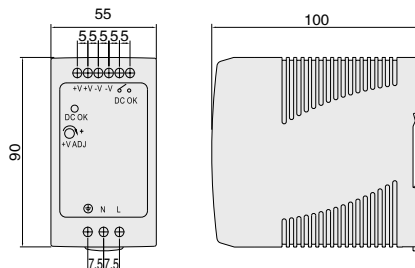

ESP20-20-*(20W)

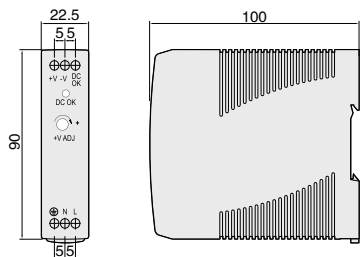

ESP20-120-*(120W)

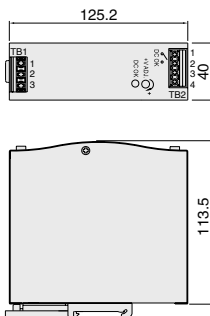


端子脚位定义 (TB1)

引脚编号	引脚功能
1	FG ⊕
2	AC/N
3	AC/L


端子脚位定义 (TB2)

引脚编号	引脚功能
1, 2	继电器触点
3	DC OUTPUT-V
4	DC OUTPUT+V

ESP20-40-*(40W)

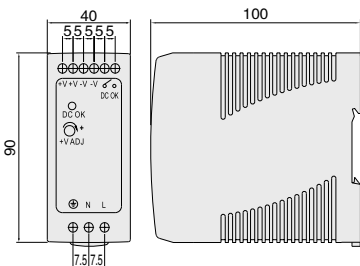

ESP20-240-*(240W)

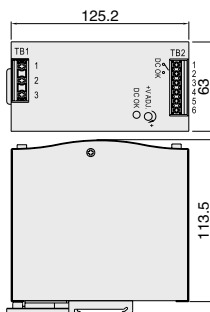


端子脚位定义 (TB1)

引脚编号	引脚功能
1	FG ⊕
2	AC/N
3	AC/L


端子脚位定义 (TB2)

引脚编号	引脚功能
1, 2	继电器触点
3, 4	DC OUTPUT+V
5, 6	DC OUTPUT-V

ESP20-60-*(60W)

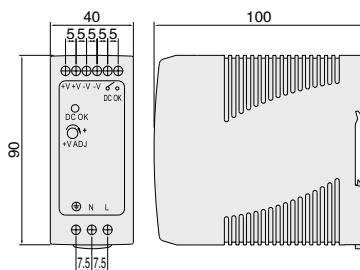

ESP20-480-*(480W)

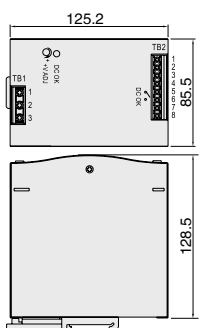

端子脚位定义 (TB1)

引脚编号	引脚功能
1	FG ⊕
2	AC/N
3	AC/L

端子脚位定义 (TB2)

引脚编号	引脚功能
1, 2	DC OUTPUT+V
3, 4	DC OUTPUT-V
5, 6	继电器触点
7, 8	NC