



FCN 线束 固定长 (使用富士通制连接器)



PLC

3.7mm O



Delivery

| | |
|------------|-------------|
| 1 ! | |
| 1~10 | () |
| 11 ~ | |
| 17:00 | |
| L (m) | 0.5 1~3 |
| | +20mm +50mm |




即时报价 b 0208



Order


| | | | |
|------|------------|------------|----|
| 1~10 | 11~30 | 31~50 | 51 |
| | 9.5 | 9.0 | |

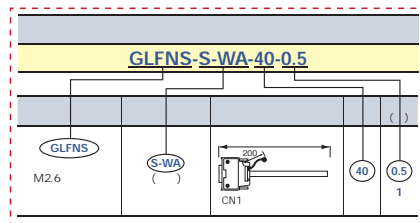

| | | | | |
|--------------------------|-------------------------|-----------|---------------------------|-----|
| | | | | () |
| GLFNS M2.6 | S-WA () | 40 | 0.5 1 2 3 | |
| | SS-WA () | | 0.5 1 2 | |


FCN


| | |
|------|------------|
| | <DC3A |
| | <250V(AC) |
| (1) | AC 500V |
| | PET() () |
| | -55 ~+85 |

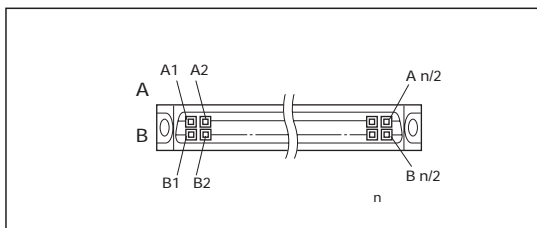

| | |
|--------|----------|
| UL No. | 20276 |
| AWG | 28 |
| | PVC |
| | PVC |
| | <246 /km |
| | 30V |
| (1) | AC 500V |
| | >10m /km |
| | -25 ~+80 |

| | | |
|----------|-----|-------|
| (mm±0.2) | | |
| 40 (20P) | 7.8 | 1.23A |

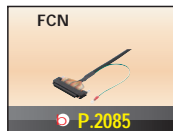

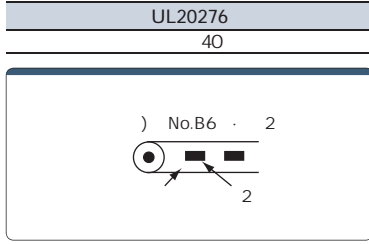

| No. | No. | | | No. |
|-----|-----|--|---|-----|
| 1 | A1 | | 1 | A1 |
| | B1 | | 1 | B1 |
| 2 | A2 | | 1 | A2 |
| | B2 | | 1 | B2 |
| 3 | A3 | | 1 | A3 |
| | B3 | | 1 | B3 |
| 4 | A4 | | 1 | A4 |
| | B4 | | 1 | B4 |
| 5 | A5 | | 1 | A5 |
| | B5 | | 1 | B5 |
| 6 | A6 | | 2 | A6 |
| | B6 | | 2 | B6 |
| 7 | A7 | | 2 | A7 |
| | B7 | | 2 | B7 |
| 8 | A8 | | 2 | A8 |
| | B8 | | 2 | B8 |
| 9 | A9 | | 2 | A9 |
| | B9 | | 2 | B9 |
| 10 | A10 | | 2 | A10 |
| | B10 | | 2 | B10 |
| 11 | A11 | | 3 | A11 |
| | B11 | | 3 | B11 |
| 12 | A12 | | 3 | A12 |
| | B12 | | 3 | B12 |
| 13 | A13 | | 3 | A13 |
| | B13 | | 3 | B13 |
| 14 | A14 | | 3 | A14 |
| | B14 | | 3 | B14 |
| 15 | A15 | | 3 | A15 |
| | B15 | | 3 | B15 |
| 16 | A16 | | 4 | A16 |
| | B16 | | 4 | B16 |
| 17 | A17 | | 4 | A17 |
| | B17 | | 4 | B17 |
| 18 | A18 | | 4 | A18 |
| | B18 | | 4 | B18 |
| 19 | A19 | | 4 | A19 |
| | B19 | | 4 | B19 |
| 20 | A20 | | 4 | A20 |
| | B20 | | 4 | B20 |

