



FCN 线束 固定长 (使用富士通制连接器)



PLC


3.7mm O



1 !	
1~10	()
11 ~	
17:00	
L (m)	0.5 1~3
	+20mm +50mm

即时报价 b 0208


1~10	11~30	31~50	51
	9.5	9.0	

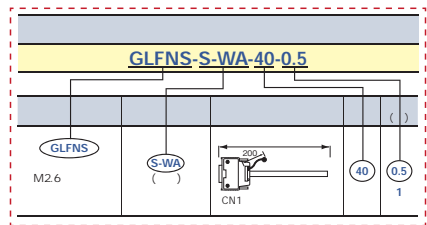

				()
GLFNS M2.6 	S-WA () 	40		0.5 1 2 3
	SS-WA () 			0.5 1 2

FCN

	<DC3A
	<250V(AC)
(1)	AC 500V
	PET() ()
	-55 ~+85

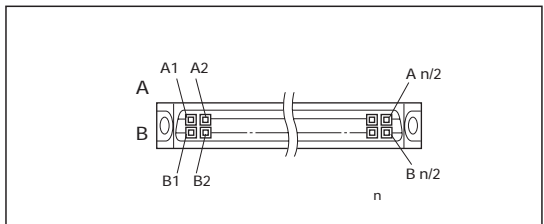


UL No.	20276
AWG	28
	PVC
	PVC
	<246 /km
	30V
(1)	AC 500V
	>10m /km
	-25 ~+80

(mm±0.2)		
40 (20P)	7.8	1.23A

2013.11
2014.10

P.3915
 P.2081
 P.2085
 P.2091

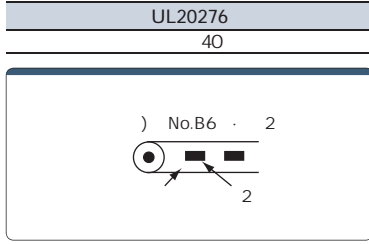

No.	No.			No.
1	A1		1	A1
	B1		1	B1
2	A2		1	A2
	B2		1	B2
3	A3		1	A3
	B3		1	B3
4	A4		1	A4
	B4		1	B4
5	A5		1	A5
	B5		1	B5
6	A6		2	A6
	B6		2	B6
7	A7		2	A7
	B7		2	B7
8	A8		2	A8
	B8		2	B8
9	A9		2	A9
	B9		2	B9
10	A10		2	A10
	B10		2	B10
11	A11		3	A11
	B11		3	B11
12	A12		3	A12
	B12		3	B12
13	A13		3	A13
	B13		3	B13
14	A14		3	A14
	B14		3	B14
15	A15		3	A15
	B15		3	B15
16	A16		4	A16
	B16		4	B16
17	A17		4	A17
	B17		4	B17
18	A18		4	A18
	B18		4	B18
19	A19		4	A19
	B19		4	B19
20	A20		4	A20
	B20		4	B20

