

タイミングベルト(MXL・XL・L・H) 同步齿形带(MXL・XL・L・H)


■同步齿形带MXL・XL・L・H适用于同步带轮MLX・XL・L・H P.797~P.804.

请按照选型步骤①~④选择型式和参数后进行订购。

Order 订货范例
型式 ①Type · ②皮带编号 · ③皮带公称宽度
TBN236MXL025



TBN(橡胶)
TUN(聚氨酯)

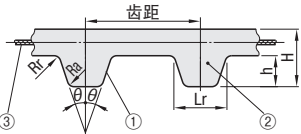

Type	①齿面保护层	②齿橡胶	③芯线	④主体	⑤芯线	材质
TBN	①齿面保护层	②齿橡胶	③芯线	④主体	⑤芯线	尼龙帆布 氯丁橡胶 玻璃纤维线S·Z形捻交互连续
TUN	①齿面保护层	②齿橡胶	③芯线	④主体	⑤芯线	聚氨酯 MXL: kevlar XL·L: 钢丝

种类	齿距	2F	Lr	h	H	Rr	Ra	单位重量 g/m(宽度: 10mm)
MXL(橡胶)	2.032	40	1.14	0.51	1.11	0.13	0.13	11.0
MXL(聚氨酯)	2.032	60	—	0.46	1.22	—	—	10.0
XL	5.08	50	2.57	1.27	2.27	0.38	0.38	22.0(20.0)
L	9.525	40	4.65	1.91	3.61	0.51	0.51	32.0(30.0)
H	12.7	40	6.12	2.28	4.58	1.00	1.00	40.0

- ①使用温度 橡胶: -30~90℃ 聚氨酯: 0~80℃
- ②为抑制橡胶飞散, 将MXL、XL橡胶皮带(TBN)的部分齿表面由黑色变更为茶色, 但不影响产品性能。
- ③同步齿形带的皮带编号数字的含义因种类而异, 敬请注意。
- ※MXL的皮带齿数为皮带编号, XL·L·H的皮带齿数为皮带周长的英制尺寸。
- ④皮带周长为芯线长度。
- ⑤TUN的XL、L型使用时不可从背面张紧。
- ⑥特长·注意事项见P.795 ⑦选择方法见P.2509

■种类 MXL (齿距: 2.032mm)

Type	型式	②皮带编号	③皮带公称宽度	齿数	皮带周长(mm)
	45MXL			45	91.44
	48MXL			48	97.54
	50MXL			50	101.60
	52MXL			52	105.66
	53MXL			53	107.70
	54MXL			54	109.73
	55MXL			55	111.76
	56MXL			56	113.79
	57MXL			57	115.82
	59MXL			59	119.89
	60MXL			60	121.92
	61MXL			61	123.95
	63MXL			63	128.02
	65MXL			65	132.08
	67MXL			67	136.14
	68MXL			68	138.18
	70MXL			70	142.24
	71MXL			71	144.27
	72MXL			72	146.30
	73MXL			73	148.34
	75MXL			75	152.40
	76MXL			76	154.43
	77MXL			77	156.46
	78MXL			78	158.50
	79MXL			79	160.53
	80MXL			80	162.56
	82MXL			82	166.62
	83MXL			83	168.66
	85MXL			85	172.72
	87MXL			87	176.78
	88MXL			88	178.82
	90MXL			90	182.88
	91MXL			91	184.91
	92MXL			92	186.94
	93MXL			93	188.98
	94MXL			94	191.01
	95MXL			95	193.04
	96MXL			96	195.07
	97MXL			97	197.10
	98MXL			98	199.14
	99MXL			99	201.17
	100MXL			100	203.20
	101MXL			101	205.23
	102MXL			102	207.26
	103MXL			103	209.30
	105MXL			105	213.36
	106MXL			106	215.39
	108MXL			108	219.46
	110MXL			110	223.52
	112MXL			112	227.58
	114MXL			114	231.65
	115MXL			115	233.68
	118MXL			118	239.74
	120MXL			120	243.80
	121MXL			121	245.83
	122MXL			122	247.86
	123MXL			123	249.89
	125MXL			125	254.00
	126MXL			126	256.03
	127MXL			127	258.06
	128MXL			128	260.10
	129MXL			129	262.13
	130MXL			130	264.16
	131MXL			131	266.19
	132MXL			132	268.22
	134MXL			134	272.29
	135MXL			135	274.32
	136MXL			136	276.35
	140MXL			140	284.44
	142MXL			142	288.54
	144MXL			144	292.64
	146MXL			146	296.74
	148MXL			148	300.84
	150MXL			150	304.90

Type	型式	②皮带编号	③皮带公称宽度	齿数	皮带周长(mm)
	155MXL			155	314.96
	158MXL			158	321.06
	160MXL			160	325.12
	162MXL			162	329.18
	165MXL			165	335.28
	170MXL			170	345.40
	175MXL			175	355.60
	180MXL			180	365.76
	184MXL			184	373.89
	190MXL			190	386.08
	192MXL			192	390.14
	195MXL			195	396.24
	200MXL			200	406.40
	210MXL			210	426.72
	212MXL			212	430.78
	221MXL			221	449.07
	222MXL			222	451.10
	224MXL			224	455.17
	226MXL			226	459.23
	228MXL			228	463.30
	230MXL			230	467.36
	232MXL			232	471.42
	236MXL			236	479.55
	239MXL			239	485.65
	240MXL			240	487.68
	245MXL			245	497.84
	248MXL			248	503.94
	250MXL			250	508.00
	256MXL			256	520.19
	260MXL			260	528.32
	262MXL			262	532.38
	265MXL			265	538.48
	273MXL			273	554.74
	275MXL			275	558.80
	280MXL			280	568.96
	281MXL			281	570.99
	285MXL			285	579.12
	288MXL			288	585.22
	290MXL			290	589.28
	295MXL			295	599.44
	297MXL			297	603.50
	300MXL			300	609.60
	305MXL			305	619.76
	310MXL			310	629.92
	312MXL			312	633.98
	315MXL			315	640.08
	318MXL			318	646.18
	320MXL			320	650.24
	330MXL			330	670.56
	332MXL			332	674.62
	334MXL			334	678.69
	336MXL			336	682.75
	337MXL			337	684.78
	347MXL			347	705.10
	350MXL			350	711.20
	355MXL			355	721.36
	359MXL			359	729.49
	364MXL			364	739.65
	365MXL			365	741.68
	372MXL			372	755.90
	380MXL			380	772.16
	397MXL			397	806.70
	400MXL			400	812.80
	405MXL			405	822.96
	435MXL			435	883.92
	448MXL			448	910.34
	453MXL			453	920.50
	464MXL			464	942.85
	467MXL			467	949.50
	498MXL			498	1011.94
	500MXL			500	1016.00
	516MXL			516	1048.51
	525MXL			525	1066.80
	535MXL			535	1087.12
	550MXL			550	1117.60

Type	型式	②皮带编号	③皮带公称宽度	齿数	皮带周长(mm)
	77MXL			77	156.46
	78MXL			78	158.50
	80MXL			80	162.56
	82MXL			82	166.62
	83MXL			83	168.66
	85MXL			85	172.72
	87MXL			87	176.78
	89MXL			89	180.85
	90MXL			90	182.88
	91MXL			91	184.91
	94MXL			94	191.01
	95MXL			95	193.04
	98MXL			98	199.14
	99MXL			99	201.17
	100MXL			100	203.20
	102MXL			102	207.26
	103MXL			103	209.30
	104MXL			104	211.33
	105MXL			105	213.36
	106MXL			106	215.39
	110MXL			110	223.52
	112MXL			112	227.58
	114MXL			114	231.65
	115MXL			115	233.68
	118MXL			118	239.74
	120MXL			120	243.80
	122MXL			122	247.86
	123MXL			123	249.89
	124MXL			124	251.92
	125MXL			125	254.00
	126MXL			126	256.03
	130MXL			130	264.16
	132MXL			132	268.22
	140MXL			140	284.44
	142MXL			142	288.54
	144MXL			144	292.64
	145MXL			145	294.64
	150MXL			150	304.90
	155MXL			155	314.96
	160MXL			160	325.12
	165MXL			165	335.28
	170MXL			170	345.44
	175MXL			175	355.60
	180MXL			180	365.76
	184MXL			184	373.89
	190MXL			190	386.08
	195MXL			195	396.24
	200MXL			200	406.40
	210MXL			210	426.72
	212MXL			212	430.78
	221MXL			221	449.07
	224MXL			224	455.17
	225MXL			225	457.20
	235MXL			235	473.55
	239MXL			239	485.65
	240MXL			240	487.68
	248MXL			248	503.94
	249MXL			249	505.97
	250MXL			250	508.00
	256MXL			256	520.19
	260MXL			260	528.32
	265MXL			265	538.48
	277MXL			277	562.86
	280MXL			280	568.96
	290MXL			290	589.28
	296MXL			296	601.47
	300MXL			300	609.60
	310MXL			310	629.92
	315MXL			315	640.08
	340MXL			340	690.88
	350MXL			350	711.20
	358MXL			358	727.46
	360MXL			360	731.52
	370MXL			370	751.84
	380MXL			380	772.16
	390MXL			390	792.48
	400MXL			400	812.80
	420MXL			420	853.44
	434MXL			434	881.89
	500MXL			500	1016.00