

高扭矩同步齿形带 (S2M · S3M · S5M · S8M · S14M)


高扭矩同步齿形带适用于高扭矩同步带轮 P805~P812。

请按照选型步骤 ①~④ 选择型式和参数后进行订购。


Order 订货范例

型式 (Type) · 皮带编号 - 皮带公称宽度

HTBN400S2M - 40

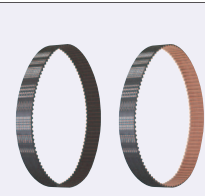

HTBN(橡胶)
HTUN(聚氨酯)

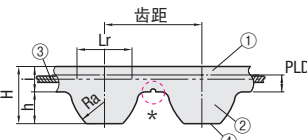

Type	①背面橡胶	②齿橡胶	③芯线	④底布	①②④主体	③芯线	材质
HTBN	①背面橡胶	②齿橡胶	③芯线	④底布	①②④主体	③芯线	氯丁橡胶 氯丁橡胶 玻璃纤维S·Z形捻交互连续 尼龙织布
HTUN	①②④主体	③芯线					聚氨酯 芳族聚酰胺纤维

种类	齿距	Re	Lr	H	h	i	PLD	单位重量 g/m (厚度: 10mm)
S2M	2	1.3	1.3	1.36	0.76	0.6	0.254	13.0(11.0)
S3M	3	1.95	1.95	1.94	1.14	0.8	0.381	19.0(15.0)
S5M	5	3.25	3.25	3.41	1.91	1.5	0.480	34.0
S8M	8	5.2	5.2	5.3	3.05	2.25	0.686	52.0
S14M	14	9.1	9.1	10.2	5.3	4.9	1.397	100.0

注: ()内为聚氨酯的单位重量。

种类 S2M (齿距: 2mm)

Type	②皮带编号	③皮带公称宽度	齿数	皮带周长 (mm)
76 S2M			38	76
78 S2M			39	78
80 S2M			40	80
88 S2M			44	88
90 S2M			45	90
100 S2M			50	100
112 S2M			56	112
116 S2M			58	116
118 S2M			59	118
122 S2M			61	122
124 S2M			62	124
126 S2M			63	126
128 S2M			64	128
130 S2M			65	130
132 S2M			66	132
134 S2M			67	134
138 S2M			69	138
140 S2M			70	140
142 S2M			71	142
144 S2M			72	144
152 S2M			76	152
160 S2M			80	160
164 S2M			82	164
166 S2M			83	166
172 S2M			86	172
176 S2M			88	176
180 S2M			90	180
186 S2M			93	186
190 S2M			95	190
194 S2M			97	194
200 S2M			100	200
204 S2M			102	204
210 S2M			105	210
212 S2M			106	212
214 S2M			107	214
220 S2M			110	220
224 S2M			112	224
230 S2M			115	230
234 S2M			117	234
236 S2M			118	236
244 S2M			122	244
246 S2M			123	246
250 S2M			125	250
256 S2M			128	256
266 S2M			133	266
280 S2M			140	280
290 S2M			145	290
300 S2M			150	300
320 S2M			160	320
324 S2M			162	324
328 S2M			164	328
330 S2M			165	330
340 S2M			170	340
360 S2M			180	360
370 S2M			185	370
380 S2M			190	380
400 S2M			200	400
436 S2M			218	436
448 S2M			224	448
500 S2M			250	500
520 S2M			260	520
560 S2M			280	560
572 S2M			286	572
600 S2M			300	600
630 S2M			315	630
710 S2M			355	710
800 S2M			400	800
900 S2M			450	900
964 S2M			482	964
1198 S2M			598	1198
1250 S2M			625	1250
1274 S2M			637	1274
1290 S2M			645	1290

种类 S2M (齿距: 2mm)

Type	②皮带编号	③皮带公称宽度	齿数	皮带周长 (mm)
80 S2M			40	80
90 S2M			45	90
100 S2M			50	100
112 S2M			56	112
126 S2M			63	126
138 S2M			69	138
140 S2M			70	140
144 S2M			72	144
160 S2M			80	160
164 S2M			82	164
166 S2M			83	166
172 S2M			86	172
176 S2M			88	176
180 S2M			90	180
186 S2M			93	186
190 S2M			95	190
194 S2M			97	194
200 S2M			100	200
204 S2M			102	204
210 S2M			105	210
212 S2M			106	212
214 S2M			107	214
220 S2M			110	220
224 S2M			112	224
230 S2M			115	230
234 S2M			117	234
236 S2M			118	236
244 S2M			122	244
246 S2M			123	246
250 S2M			125	250
260 S2M			130	260
280 S2M			140	280
290 S2M			145	290
300 S2M			150	300
320 S2M			160	320
330 S2M			165	330
360 S2M			180	360
370 S2M			185	370
396 S2M			198	396
436 S2M			218	436
448 S2M			224	448
488 S2M			244	488
498 S2M			248	498
520 S2M			260	520
560 S2M			280	560
572 S2M			286	572
600 S2M			290	600
630 S2M			315	630
800 S2M			400	800
984 S2M			492	984
1196 S2M			598	1196
1250 S2M			625	1250
1274 S2M			637	1274

种类 S3M (齿距: 3mm)

Type	②皮带编号	③皮带公称宽度	齿数	皮带周长 (mm)
144 S3M			48	144
162 S3M			54	162
174 S3M			58	174
177 S3M			59	177
180 S3M			60	180
186 S3M			62	186
192 S3M			64	192
201 S3M			67	201
210 S3M			70	210
213 S3M			71	213
219 S3M			73	219
222 S3M			74	222
225 S3M			75	225
234 S3M			78	234
237 S3M			79	237
246 S3M			82	246
252 S3M			84	252
255 S3M			85	255
264 S3M			88	264
275 S3M			91	273
276 S3M			92	276
279 S3M			93	279
285 S3M			95	285
288 S3M			96	288
291 S3M			97	291
300 S3M			100	300
312 S3M			104	312
318 S3M			106	318
327 S3M			109	327
345 S3M			115	345
360 S3M			120	360
367 S3M			121	363
369 S3M			123	369
375 S3M			125	375
387 S3M			129	387
402 S3M			134	402
405 S3M			135	405
408 S3M			136	408
420 S3M			140	420
432 S3M			144	432
453 S3M			151	453
474 S3M			158	474
480 S3M			160	480
483 S3M			161	483
486 S3M			162	486
501 S3M			167	501
507 S3M			169	507
519 S3M			173	519
525 S3M			175	525
537 S3M			179	537
540 S3M			180	540
591 S3M			197	591
600 S3M			200	600
612 S3M			204	612
633 S3M			211	633
645 S3M			215	645
660 S3M			220	660
741 S3M			247	741
750 S3M			250	750
804 S3M			268	804
810 S3M			270	810
852 S3M			284	852
900 S3M			300	900
919 S3M			306	918
1090 S3M			360	1080
1119 S3M			373	1119
1203 S3M			401	1203
1221 S3M			407	1221
1236 S3M			412	1236
1245 S3M			415	1245
1260 S3M			420	1260
1290 S3M			430	1290
1299 S3M			433	1299
1332 S3M			444	1332
1401 S3M			467	1401
1596 S3M			532	1596
1680 S3M			560	1680
1788 S3M			596	1788
2100 S3M			700	2100

种类 S3M (齿距: 3mm)

Type	②皮带编号	③皮带公称宽度	齿数	皮带周长 (mm)
123 S3M			41	123
129 S3M			43	129
141 S3M			47	141
144 S3M			48	144
150 S3M			50	150
162 S3M			54	162
171 S3M			57	171
174 S3M			58	174
177 S3M			59	177
180 S3M			60	180
186 S3M			62	186
189 S3M			63	189
192 S3M			64	192
195 S3M			65	195
201 S3M			67	201
210 S3M			70	210
213 S3M			71	213
219 S3M			73	219
222 S3M			74	222
225 S3M			75	225
234 S3M			78	234
237 S3M			79	237
246 S3M			82	246
252 S3M			84	252
255 S3M			85	255
264 S3M			88	264
275 S3M			91	273
276 S3M			92	276
279 S3M			93	279
285 S3M			95	285
288 S3M			96	288
291 S3M			97	291
300 S3M			100	300
312 S3M			104	312
318 S3M			106	318
339 S3M			113	339
345 S3M			115	345
354 S3M			118	354
363 S3M			121	363
369 S3M			123	369
375 S3M			125	375
384 S3M			128	384
387 S3M			129	387
396 S3M			132	396
408 S3M			136	408
420 S3M			140	420
423 S3M			141	423
432 S3M			144	432
453 S3M			151	453
474 S3M			158	474
480 S3M			160	480
483 S3M			161	483
486 S3M			162	486
501 S3M			167	501
507 S3M			169	507
519 S3M			173	519
525 S3M			175	525
537 S3M			179	537